 



Counter rotating lead screws



PTGSG-10x2-R/L-100-100

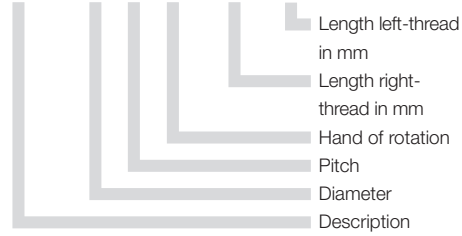

Dimensions [mm]

Part number	Thread	I4	Length
PTGSG-10x2-R/L- <input type="checkbox"/> ¹⁾ - <input type="checkbox"/> ²⁾	TR10x2	20	1,000
PTGSG-14x4-R/L- <input type="checkbox"/> ¹⁾ - <input type="checkbox"/> ²⁾	TR14x4	30	1,000
PTGSG-18x4-R/L- <input type="checkbox"/> ¹⁾ - <input type="checkbox"/> ²⁾	TR18x4	55	1,500
PTGSG-24x5-R/L- <input type="checkbox"/> ¹⁾ - <input type="checkbox"/> ²⁾	TR24x5	60	2,000

¹⁾ Length right-thread (I3)²⁾ Length left-thread (I2)



All dimensions also available in stainless steel. Please add suffix "-ES"

 delivery from stock
time prices price list online
www.igus.eu/drylin-leadscrewdrives

Metric lead screws



PTGSG-M3-01-R-500-ES

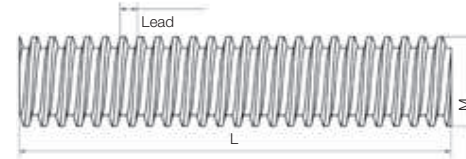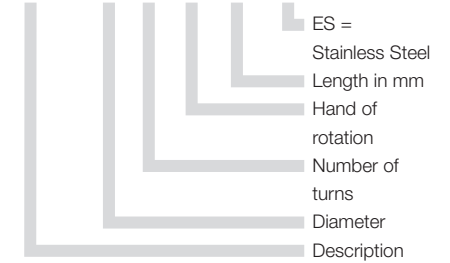

Dimensions [mm]

Bestellnummer	Thread	Diameter	Pitch	max. Length
PTGSG-M3-01-R-500-ES	M3x0.5	3	0.5	500
PTGSG-M4-01-R-500-ES	M4x0.7	4	0.7	500
PTGSG-M5-01-R-500-ES	M5x0.8	5	0.8	500
PTGSG-M6-01-R-500-ES	M6x1	6	1	500

Only available as stainless steel version

 delivery from stock
time prices price list online
www.igus.eu/drylin-leadscrewdrives