

Standard separator, wide foot

unassembled	70.1
assembled	70.1.1

Standard - for all applications
Separator with wide foot for maximum locking strength and safe standing in E-Chains® and E-Tubes.

Separator, narrow foot*

unassembled	70.3
assembled	70.3.1

For many thin cables
Separator with narrow foot for a large number of thin cables side by side. Saves space in E-Chains® and E-Tubes. Also available for QuickLock crossbars.


*available upon request. Delivery time: approx. 1-2 weeks after intake of order

Asymmetrical separator*


unassembled	70.4
assembled	70.4.1

For side-mounted applications
Asymmetrical separator, for defined distance. No additional spacers necessary for E-Chains® and E-Tubes.

*available upon request. Delivery time: approx. 1-2 weeks after intake of order

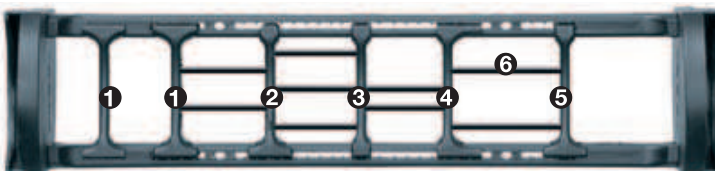

- i** ① Standard separator, wide foot - Part No. 70.1 ③ Separator, narrow foot - Part No. 70.3 ⑤ Notch separator - Part No. 70.5
② Separator for QuickLock crossbar - Part No. 70.2 ④ Separator, asymmetrical - Part No. 70.4 ⑥ Full-width shelf, lockable - Part No. 520.XX

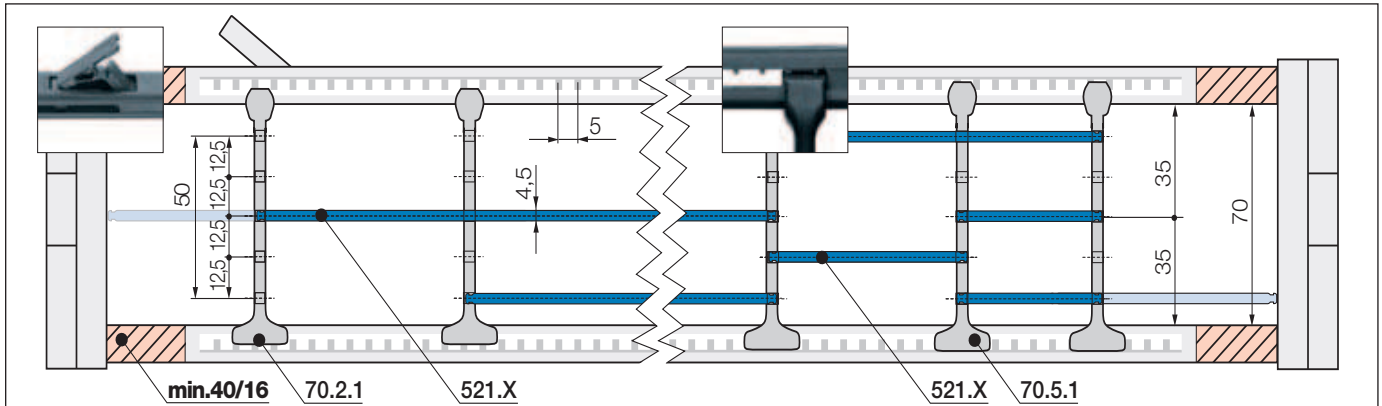

Note: Please observe a lateral spacing to the sidelinks! **E-Tube: 40 mm | E-Chain®: 16 mm**
In the standard configuration separators are assembled every 2nd E-Chain® link !

Separator for QuickLock crossbar*
unassembled **70.2**
assembled **70.2.1**

Dimensions: 8, 4, 18

For even faster installation

Separator for igus® QuickLock crossbar 450.X.Q. Firm hold to one side with a wide foot, narrow on opposed side for easy cable assembly (slight grip). For E-Tubes also.

*available upon request. Delivery time: approx. 1-2 weeks after intake of order

Notch separator for notch crossbar*
unassembled **70.5**
assembled **70.5.1**

Dimensions: 8, 4, 18

Locks safely onto in 5 mm increments

Notch separator for the new notch crossbar, with scaling on the notch crossbars. For exact positioning in E-Chains® and E-Tubes. Recommended for side-mounted applications.

*available upon request. Delivery time: approx. 1-2 weeks after intake of order


Full-width shelf, lockable
unassembled **520.X**
assembled **521.X**

Dimensions: 45, X-1

Horizontal separation

Shelf locks safely into separators on both ends, fixed width possible. Separators can be moved freely over the shelf in horizontal direction. Usable in 5 levels.

Lockable full-width shelves - for the standard interior separation

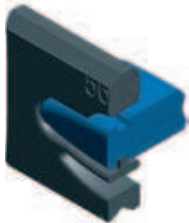

Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled	Width X [mm]	unassembled	assembled
050	520.050	521.050	125	520.125	521.125	225	520.225	521.225
062	520.062	521.062	150	520.150	521.150	250	520.250	521.250
075	520.075	521.075	175	520.175	521.175	300	520.300	521.300
100	520.100	521.100	200	520.200	521.200	450	520.450	521.450

